


Product Datasheet
29526084

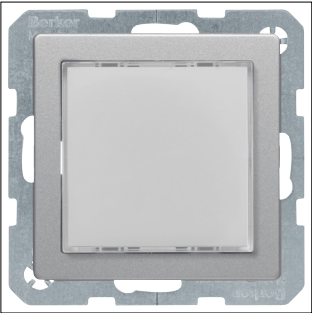

29526084



LED signal light, red/green lighting Q.x alu velvety, lacquered

Technical Features

Voltage

Rated voltage	230 V
---------------	-------

Power

Power absorbed	0.50 W
----------------	--------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Lighting

Type of lamp	LED
--------------	-----

Materials

Colour	Aluminium
RAL code	9006
Surface finish	Velvety
Material	Metal Plastic
Treatment	Varnished

Dimensions

Height	70 mm
Width	70 mm
Depth	50 mm

Connection

Conductor cross-section	2.50 - 2.50 mm²
-------------------------	-----------------

Connectivity

Mounting type	Claw mounting Screw connection
---------------	-----------------------------------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Texts

Labelling	Foil bi-colour with imprinted symbols for Do not disturb / Make up room and Enter/ Wait are supplied
Imprint	Without imprint

Suitable for

Q.x	
-----	--

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes