


Product Datasheet  
29526086

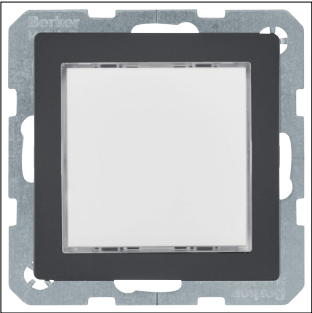

29526086



LED signal light, red/green lighting, Q.x, ant. velvety, lacq.

Technical Features

Voltage

Rated voltage230 V

Power

Power absorbed0.50 W

Frequency

Frequency50 - 60 Hz

Lighting

Type of lampLED

Materials

ColourAnthracite

RAL code7021

Surface finishVelvety

MaterialMetal  
Plastic

TreatmentVarnished

Dimensions

Height70 mm

Width70 mm

Depth50 mm

Connection

Conductor cross-section2.50 - 2.50 mm²

Connectivity

Mounting typeClaw mounting  
Screw connection

Safety

Ingress Protection (IP) classIP20

Texts

LabellingFoil bi-colour with imprinted symbols for Do not disturb / Make up room and  
Enter/ Wait are supplied

ImprintWithout imprint

Suitable for

Q.x

Sustainability

Halogen freeYes

REACH-SVHC freeYes

RoHS conformYes