


Product Datasheet

REN091X

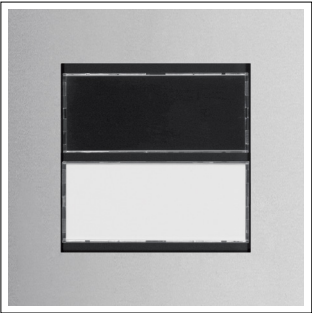

REN091X



Call push-but mod 1/1 with LED name plate and LED st ind built-in 2-wire modesta

Technical Features

Materials

Colour	Stainless steel
Material	Metal
Surface finish	Matt

Dimensions

Dimensions	120 x 120 mm
Height	120 mm
Width	120 mm
Built-in depth	22.50 mm

Voltage

Operating voltage	24 - 24 V
-------------------	-----------

Controls and indicators

Number of call buttons	1
------------------------	---

Functions

Function	Ringing
----------	---------

Settings

Number of users	1
-----------------	---

Use conditions

Operating temperature	-20 - 55 °C
Storage/transport temperature	-30 - 80 °C