
 


Product Datasheet

REN090X

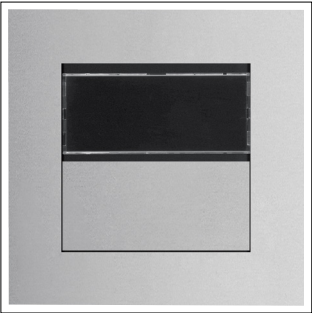

REN090X



Status indication module built-in 2-wire stainless steel matt modesta

Technical Features

Materials

Colour	Stainless steel
Material	Metal
Surface finish	Matt

Dimensions

Dimensions	120 x 120 mm
Height	120 mm
Width	120 mm
Built-in depth	22.50 mm

Voltage

Operating voltage	24 - 24 V
-------------------	-----------

Controls and indicators

Number of call buttons	0
------------------------	---

Functions

Function	Inform
----------	--------

Settings

Number of users	0
-----------------	---

Use conditions

Operating temperature	-20 - 55 °C
Storage/transport temperature	-30 - 80 °C