




80660100

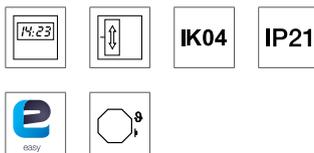

KNX room cont., colourdisplay, intg bus coupling unit, KNX

Technical Features

Installation, mounting

Mounting on Flush mounting

Use conditions

Operating temperature -5 - 45 °C

Electric current

Bus current consumption data transfer 10 mA

Dimensions

Built-in depth 32 mm
 Built-in depth flush-mounted boxes 26 mm
 Height 71 mm
 Width 71 mm
 Depth 46.70 mm

Equipment

Number of actuation points 3

Controls and indicators

With LED indication Yes

Materials

Colour Black
 RAL code 9005
 Material Thermoplastic

Screen

With display Yes

Texts

Function Deactivate automatic function
 For switch, dimmer and shutter functions
 With keylock
 With holiday switching
 With frost protection function

Installation mode With spreader claws
 For flush-mounted and hollow wall mounting
 For single mounting
 For vertical mounting

Temperature Additional connection for external temperature sensor
 Comfort, standard and night temperature
 Temperature measurement via internal and/or connectable
 Temperature sensor with average determination