


Product Datasheet

BDH380E

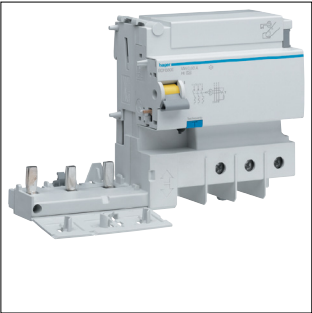

BDH380E

Earth leakage add-on-block 3P 125A 30mA type A HI

Technical Features

Electric current	
Rated current	125 A
Rated residual operating current I _{dn}	30 mA

Architecture	
Number of poles	3

Frequency	
Frequency	50 - 50 Hz

Installation, mounting	
Nominal tightening torque	3.50 - 3.50 Nm

Power	
Total power loss under I _N	11.25 W

Endurance	
Number of mechanical operations	7000
Electric endurance in number of cycles	1000

Voltage	
Rated insulation voltage U _i	500 V
Rated impulse withstand voltage U _{imp}	6000 V

Safety	
Residual current type	A HI

Capacity	
Number of modules	6

Connectivity	
Type of connection	Screw terminal
Down connection alignment for modular devices	Aligned terminal

Dimensions	
Height	103 mm
Width	187 mm
Depth	69 mm

Illustrations | Drawings

