


Product Datasheet

3036

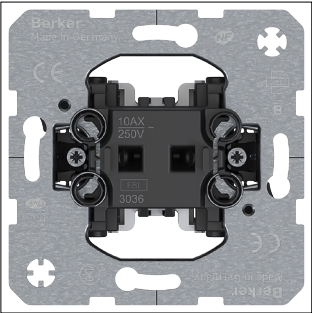

3036

Change-over switch 10AX 250V~, Light control

Technical Features

Electric current	
Switching current	10 AX (100W LED (SBL))

Installation, mounting	
Mounting on	Flush mounting

Voltage	
Rated voltage	250 V

Frequency	
Frequency	50 - 60 Hz

Materials	
Surface finish	Matt
Material	Metal Plastic

Identification	
Assembly arrangement	Basic element

Connectivity	
Mounting type	Claw mounting

Controls and indicators	
Number of buttons	1

Dimensions	
Dimensions	71 x 71 mm
Built-in depth	31 mm
Built-in depth flush-mounted boxes	35 mm

Safety	
Ingress Protection (IP) class	IP20
Impact resistance IK	IK07

Architecture	
Control/operation element	Single rocker

Electric current	
Rated current	10 A

Texts	
Installation mode	With spreader claws For screw fastening
Type of connection	With plug-in terminals
Lighting	For lighting and monitoring circuit
Switch mode	Off/change-over

Sustainability	
Halogen free	Yes
RoHS conform	Yes