


Product Datasheet

3035

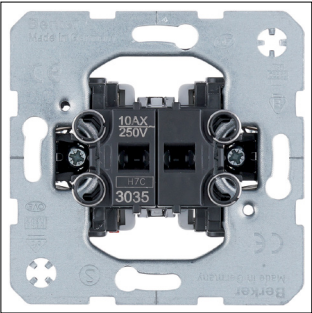

3035

Series switch

Technical Features

Electric current

Switching current10 AX (100W LED (SBL))

Installation, mounting

Mounting onFlush mounting

Voltage

Rated voltage250 V

Frequency

Frequency50 - 60 Hz

Materials

Surface finishMatt
MaterialMetal
Plastic

Identification

Assembly arrangementBasic element

Connectivity

Mounting typeClaw mounting

Controls and indicators

Number of buttons2

Dimensions

Dimensions71 x 71 mm
Built-in depth32 mm
Built-in depth flush-mounted boxes35 mm

Safety

Ingress Protection (IP) classIP20
Impact resistance IKIK07

Architecture

Control/operation elementDouble rocker

Electric current

Rated current10 A

Connection

Connector/plug typePlug clamp

Texts

Installation modeWith spreader claws
Type of connectionWith plug-in terminals
LightingFor lighting and monitoring circuit
Switch modeSeries

Sustainability

Halogen freeYes
RoHS conformYes