


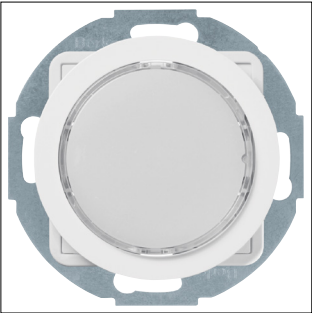

29512089



LED signal light, RGB, R.1/R.3, p. white glossy

Technical Features

Voltage

|               |       |
|---------------|-------|
| Rated voltage | 230 V |
|---------------|-------|

Power

|                |     |
|----------------|-----|
| Power absorbed | 2 W |
|----------------|-----|

Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

Lighting

|              |     |
|--------------|-----|
| Type of lamp | LED |
|--------------|-----|

Materials

|                |                  |
|----------------|------------------|
| Colour         | Polar white      |
| RAL code       | 9010             |
| Surface finish | Glossy           |
| Material       | Metal<br>Plastic |
| Treatment      | Untreated        |

Dimensions

|        |       |
|--------|-------|
| Height | 70 mm |
| Width  | 70 mm |
| Depth  | 50 mm |

Connection

|                         |                             |
|-------------------------|-----------------------------|
| Conductor cross-section | 2.50 - 2.50 mm <sup>2</sup> |
|-------------------------|-----------------------------|

Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
|-------------------------------|------|

Texts

|           |                                                                                                                                                                                                       |
|-----------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Lighting  | Light colours cold white, warm white, blue, orange, red, green, purple (magenta) and colour sequence callable via push-button.<br>Colour sequence can be stopped at any position via the push-button. |
| Labelling | Foils with imprint of symbols insertable                                                                                                                                                              |
| Imprint   | Without imprint                                                                                                                                                                                       |