


Product Datasheet  
29512089

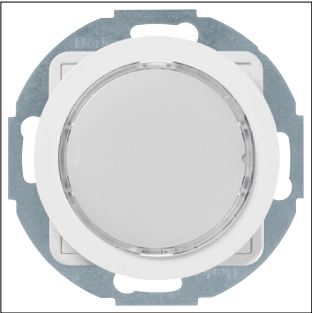

29512089



LED signal light, RGB, R.1/R.3, p. white glossy

Technical Features

Voltage

Rated voltage230 V

Power

Power absorbed2 W

Frequency

Frequency50 - 60 Hz

Lighting

Type of lampLED

Materials

Colour	Polar white
RAL code	9010
Surface finish	Glossy
Material	Metal Plastic
Treatment	Untreated

Dimensions

Height	70 mm
Width	70 mm
Depth	50 mm

Connection

Conductor cross-section2.50 - 2.50 mm²

Safety

Ingress Protection (IP) classIP20

Texts

Lighting	Light colours cold white, warm white, blue, orange, red, green, purple (magenta) and colour sequence callable via push-button Colour sequence can be stopped at any position via the push-button.
Labelling	Foils with imprint of symbols insertable
Imprint	Without imprint