


Product Datasheet

389303

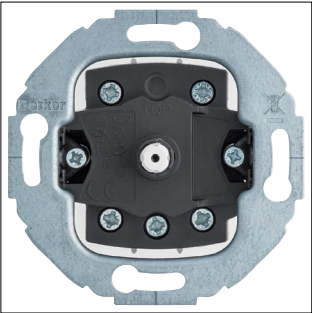

389303

Rotary switch, 2p off, S1930/Glas/R.clas

Technical Features

Electric current	
Switching current	10 AX (100W LED (SBL))

Installation, mounting	
Mounting on	Flush mounting

Voltage	
Rated voltage	250 V

Materials	
Material	Duroplastic

Identification	
Assembly arrangement	Basic element

Connectivity	
Mounting type	Claw mounting

Dimensions	
Dimensions	71 x 71 mm
Built-in depth	31 mm
Built-in depth flush-mounted boxes	35 mm

Safety	
Ingress Protection (IP) class	IP20

Architecture	
Control/operation element	Short rotary handle

Electric current	
Rated current	10 A

Texts	
Installation mode	With spreader claws
Type of connection	With screw terminals
Lighting	Without neon lamp
Switch mode	2-pole off

Sustainability	
RoHS conform	Yes