


Product Datasheet

29536089

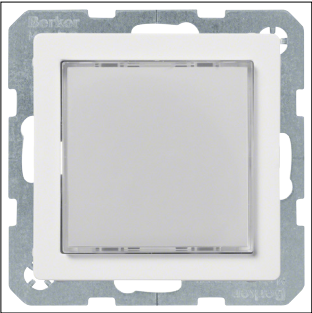

29536089



LED signal light, white lighting, Q.x, p. white velvety

Technical Features

Voltage

Rated voltage	230 V
---------------	-------

Power

Power absorbed	1 W
----------------	-----

Frequency

Frequency	50 - 60 Hz
-----------	------------

Lighting

Type of lamp	LED
--------------	-----

Materials

Colour	Polar white
RAL code	9010
Surface finish	Velvety
Material	Metal Plastic
Treatment	Untreated

Dimensions

Height	70 mm
Width	70 mm
Depth	50 mm

Connection

Conductor cross-section	2.50 - 2.50 mm ²
-------------------------	-----------------------------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Texts

Lighting	Light colour cold white
Labelling	Foils with imprint of symbols insertable
Imprint	Without imprint

Suitable for

Q.x	
-----	--

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes