


Product Datasheet  
29536086

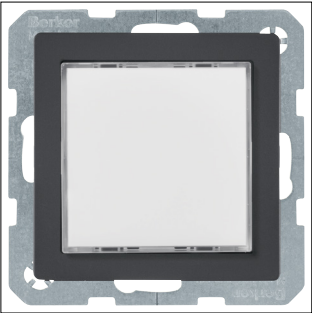

29536086



LED signal light, white lighting, Q.x, ant. velvety, lacq.

Technical Features

Voltage

Rated voltage230 V

Power

Power absorbed1 W

Frequency

Frequency50 - 60 Hz

Lighting

Type of lampLED

Materials

ColourAnthracite

RAL code7021

Surface finishVelvety

MaterialMetal  
Plastic

TreatmentVarnished

Dimensions

Height70 mm

Width70 mm

Depth50 mm

Connection

Conductor cross-section2.50 - 2.50 mm<sup>2</sup>

Connectivity

Mounting typeClaw mounting  
Screw connection

Safety

Ingress Protection (IP) classIP20

Texts

LightingLight colour cold white

LabellingFoil with imprint of symbols insertable

ImprintWithout imprint

Suitable for

Q.x

Sustainability

REACH-SVHC freeYes

RoHS conformYes