


# Product Datasheet

## KB463A

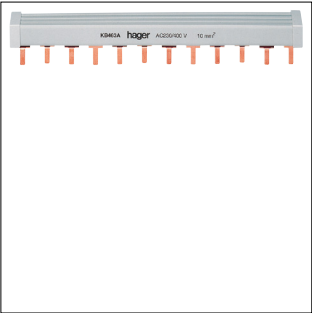

KB463A

### Insulated busbar 3P+N 63A prong 10mm<sup>2</sup> 12M

#### Technical Features

##### Electric current

|               |      |
|---------------|------|
| Rated current | 63 A |
|---------------|------|

##### Architecture

|                 |   |
|-----------------|---|
| Number of poles | 4 |
|-----------------|---|

##### Dimensions

|        |        |
|--------|--------|
| Length | 210 mm |
|--------|--------|

##### Voltage

|                                      |             |
|--------------------------------------|-------------|
| Rated impulse withstand voltage Uimp | 4000 V      |
| Rated operational voltage Ue         | 230 - 400 V |

##### Connection

|                               |                       |
|-------------------------------|-----------------------|
| Cross-section rigid conductor | 10 mm <sup>2</sup>    |
| Connector/plug type           | Phase busbar with pin |

##### Capacity

|                   |    |
|-------------------|----|
| Number of modules | 12 |
|-------------------|----|

##### Sustainability

|              |     |
|--------------|-----|
| RoHS conform | Yes |
|--------------|-----|