


Product Datasheet

KB463C

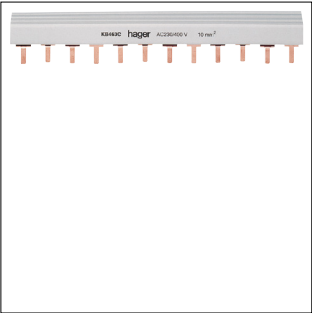

KB463C

Insulated busbar 3P+N 63A prong 10mm² 24M

Technical Features

Electric current

Rated current	63 A
---------------	------

Architecture

Number of poles	4
-----------------	---

Dimensions

Length	420 mm
--------	--------

Voltage

Rated impulse withstand voltage Uimp	4000 V
Rated operational voltage Ue	230 - 400 V

Connection

Cross-section rigid conductor	10 mm²
Connector/plug type	Phase busbar with pin

Capacity

Number of modules	24
-------------------	----

Sustainability

RoHS conform	Yes
--------------	-----