


Product Datasheet

WGDL121PEG

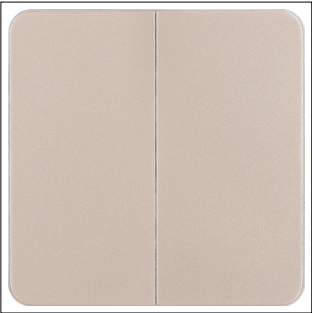

WGDL121PEG

10A 2G press switch;eg

Technical Features

Electric current

Switching current	10 A
-------------------	------

Voltage

Rated voltage	250 V
---------------	-------

Architecture

Control/operation element	Double rocker
---------------------------	---------------

Materials

Colour	Gold
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Varnished
Transparent	No

Dimensions

Height	86 mm
Width	86 mm
Depth	25 mm
Built-in depth flush-mounted boxes	35 mm

Controls and indicators

Number of buttons	2
With feedback signal contact	No

Connectivity

Type of connection	Screw terminal
--------------------	----------------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Texts

Switch mode	1-way
-------------	-------

Suitable for

shark	
-------	--

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes