


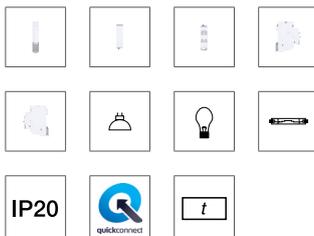

EMS005



Multifunction stair case time lag switch

Technical Features

Voltage

Rated operational voltage Ue 230 - 230 V

Frequency

Frequency 50 - 60 Hz

Electric current

Rated current 16 A

Capacity

Number of modules 1

Connectivity

Type of connection quickconnect
Wire connection

Installation, mounting

Mounting on DIN rail

Lighting

Max. load fluorescent lamp parallel compensated 1000 VA

Max. load fluorescent lamp 3600 VA

Use conditions

Operating temperature -10 - 55 °C

Connection

Cross-section flexible conductor 1.5 - 2.5 mm²

Cross-section rigid conductor 1.5 - 2.5 mm²

Settings

Time delay 30 S - 10 Min

Dimensions

Width 17.50 mm

Depth 64 mm

Power

230 V incandescent and halogen lamp 2300 W

Texts

Junction For 3 and 4-conductor circuit (automatic detection)

Switch mode NO contact

Installation mode For mounting on DIN rail

Type of connection With quickconnect plug-in terminals

Function With switch-off advance warning: Flashing at 40, 30 seconds before switching off
With potentiometer for setting time functions: automatic/automatic With switch-off advance warning/automatic with selectable long time operation (1 h)/automatic
With selectable long time operation (1 h) and switch-off advance warning