


Product Datasheet

286210

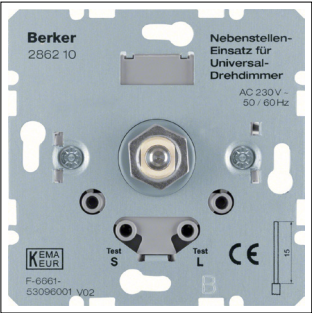

286210

Extension units insert for universal rot. dimmer, soft-lock, light control

Technical Features

Voltage

Operating voltage 230 - 230 V

Frequency

Frequency 50 - 60 Hz

Materials

Material Metal Plastic

Dimensions

Diameter axis	4 mm
Height	71 mm
Width	71 mm
Depth	50 mm

Architecture

Control/operation element Push & rotative switch

Texts

Voltage	Voltage test possible without dismantling
Installation mode	With spreader claws
Type of connection	With plug-in terminals

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes