


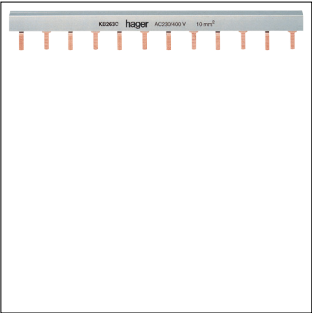

KB263C

Insulated busbar 2P 63A prong 10mm² 24M

Technical Features

Electric current	
Rated current	63 A
Architecture	
Number of poles	2
Dimensions	
Length	420 mm
Voltage	
Rated impulse withstand voltage Uimp	4000 V
Rated operational voltage Ue	230 - 400 V
Connection	
Cross-section rigid conductor	10 mm ²
Connector/plug type	Phase busbar with pin
Capacity	
Number of modules	24
Sustainability	
RoHS conform	Yes