


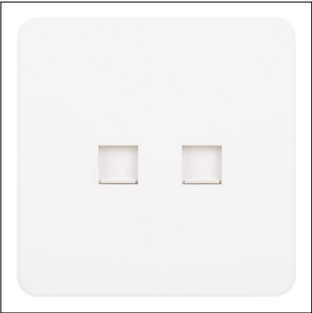

WGDT2RJ6NM

RJ45 outlet cat6 (2mod) wo/symbol

Technical Features

Frequency

|                        |           |
|------------------------|-----------|
| Transmission bandwidth | 0-250 MHz |
|------------------------|-----------|

Equipment

|                               |    |
|-------------------------------|----|
| With transparent label holder | No |
| Number of outputs             | 2  |

Use conditions

|                       |           |
|-----------------------|-----------|
| Operating temperature | -20-45 °C |
|-----------------------|-----------|

Equipment

|                 |    |
|-----------------|----|
| With hinged lid | No |
|-----------------|----|

Materials

|        |       |
|--------|-------|
| Colour | White |
|--------|-------|

Connection

|                     |      |
|---------------------|------|
| Connector/plug type | RJ45 |
|---------------------|------|

Materials

|          |                    |
|----------|--------------------|
| Material | Polycarbonate (PC) |
|----------|--------------------|

Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
|-------------------------------|------|

Voltage

|               |     |
|---------------|-----|
| Rated voltage | 0 V |
|---------------|-----|

Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |