


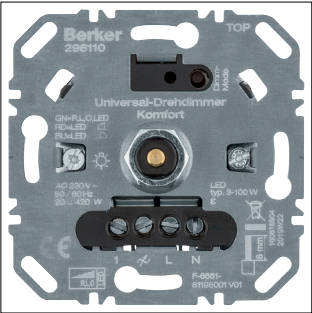

296110

Universal rotary dimmer comfort (R, L, C, LED), soft-lock, light control

Technical Features

Voltage	
Operating voltage	230 - 230 V
Frequency	
Frequency	50 - 60 Hz
Materials	
Material	Metal Plastic

Dimensions	
Diameter axis	4 mm
Built-in depth	24 mm
Height	71 mm
Width	71 mm
Depth	43 mm

Architecture	
Control/operation element	Push & rotative switch

Lighting	
Dimmable 230 V LED lamp	3 - 100 W

Texts	
Dimming principle	Phase cut-on, cut-off or LED phase cut-on according to load type, self-learning
Fuse	Short-circuit and overload-proof (electronic fuse)
Voltage	Voltage test possible without dismantling
Installation mode	With spreader claws
Type of connection	With screw terminals
Extension unit input	With extension unit input for push-button (NO contact) With single-surface operation With input for extension units insert for universal rotary dimmer
Operation and control	No Bluetooth interface

Sustainability	
REACH-SVHC free	Yes
RoHS conform	Yes