


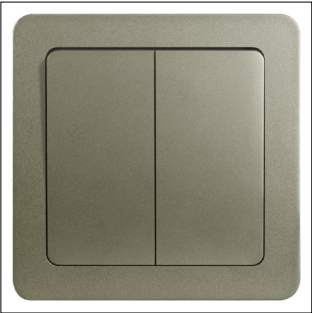

WGCXL122NB

16AX 2G 2W switch;nb

Technical Features

|                         |      |
|-------------------------|------|
| <b>Electric current</b> |      |
| Switching current       | 16 A |

|                |       |
|----------------|-------|
| <b>Voltage</b> |       |
| Rated voltage  | 250 V |

|                  |                    |
|------------------|--------------------|
| <b>Materials</b> |                    |
| Colour           | Bronze             |
| Surface finish   | Matt               |
| Material         | Polycarbonate (PC) |
| Treatment        | Varnished          |

|                                |   |
|--------------------------------|---|
| <b>Controls and indicators</b> |   |
| Number of buttons              | 2 |

|                                    |            |
|------------------------------------|------------|
| <b>Dimensions</b>                  |            |
| Dimensions                         | 86 x 86 mm |
| Built-in depth flush-mounted boxes | 35 mm      |

|                               |      |
|-------------------------------|------|
| <b>Safety</b>                 |      |
| Ingress Protection (IP) class | IP20 |

|                           |                    |
|---------------------------|--------------------|
| <b>Architecture</b>       |                    |
| Control/operation element | Double push button |

|                         |      |
|-------------------------|------|
| <b>Electric current</b> |      |
| Rated current           | 16 A |

|              |       |
|--------------|-------|
| <b>Texts</b> |       |
| Switch mode  | 2-way |

|                       |     |
|-----------------------|-----|
| <b>Sustainability</b> |     |
| RoHS conform          | Yes |