


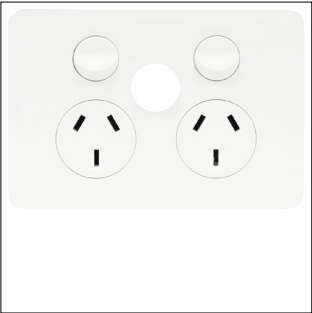

WBHP2XSB

Allure DGPO 10A XS Pos no mech

Technical Features

Electric current

|               |      |
|---------------|------|
| Rated current | 10 A |
|---------------|------|

Voltage

|                 |             |
|-----------------|-------------|
| Nominal voltage | 250 - 250 V |
|-----------------|-------------|

Materials

|        |       |
|--------|-------|
| Colour | White |
|--------|-------|

Connectivity

|               |                |
|---------------|----------------|
| Mounting type | Screw mounting |
|---------------|----------------|

Equipment

|                                   |                                 |
|-----------------------------------|---------------------------------|
| Connector/plug type socket outlet | Australian standard AS/NZS 3112 |
| Rotated central insert            | No                              |
| With hinged lid                   | No                              |

Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP2X |
|-------------------------------|------|

Texts

|                    |                      |
|--------------------|----------------------|
| Cover              | Full cover plate     |
| Type of connection | With screw terminals |

Suitable for

|        |  |
|--------|--|
| allure |  |
|--------|--|

Sustainability

|                 |     |
|-----------------|-----|
| Halogen free    | Yes |
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |