




EE110

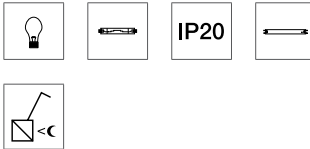

Twilight switch, daily cycle

Technical Features

Frequency

Frequency 50 - 60 Hz

Voltage

Rated operational voltage Ue 230 - 230 V

Settings

Switch on delay time 15 s

Use conditions

Operating temperature -10 - 50 °C

Storage/transport temperature -20 - 60 °C

Connection

Cross-section flexible conductor 0.5 - 4 mm²

Cross-section rigid conductor 0.5 - 4 mm²

Capacity

Number of modules 5

Texts

Installation mode For mounting on DIN rail
Extension sensor for wall and ceiling mounting

Type of connection With screw terminals

Dimensions

Height 85 mm

Width 88 mm

Depth 65 mm