


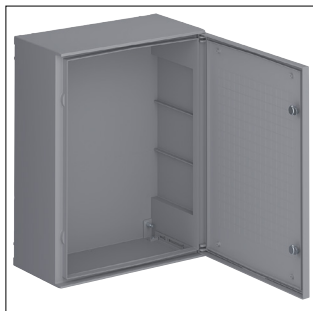

FL221B

Polyester enclosure, Orion.Plus, plain door 650x500x250 mm

Technical Features

Dimensions

Height	650 mm
Width	500 mm
Depth	250 mm
Thickness of sidewall	2 mm

Safety

Ingress Protection (IP) class	IP66
Protection class	Isolation class II
Locking type	3-Side 7 mm Key lock
Impact resistance IK	IK10

Equipment

Number of flange plate openings	0
---------------------------------	---

Installation, mounting

Mounting on	Surface mounting
Suitable for outdoor usage	Yes

Materials

Colour	Light grey
RAL code	7035
Treatment	Untreated
Material	Glass reinforced polyester

Equipment

Number of rows	4
----------------	---

Cover, door

Number of cabinet doors	1
Number of locks	2
Door/cover is transparent	No

Electric current

Rated current	125 A
---------------	-------

Sustainability

Halogen free	Yes
RoHS conform	Yes