


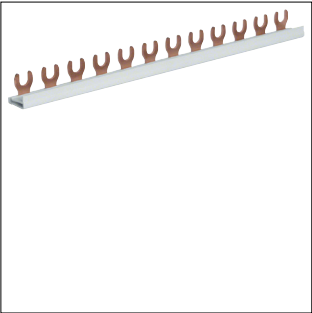

KDN163A

Insulated busbar 1P 63A fork 10mm² 12M

Technical Features

Electric current

Rated current	63 A
---------------	------

Architecture

Number of poles	1
-----------------	---

Dimensions

Length	210 mm
--------	--------

Voltage

Rated impulse withstand voltage Uimp	4500 V
--------------------------------------	--------

Rated operational voltage Ue	415 - 415 V
------------------------------	-------------

Connection

Cross-section rigid conductor	10 mm ²
-------------------------------	--------------------

Connector/plug type	Phase busbar with fork
---------------------	------------------------

Capacity

Number of modules	12
-------------------	----

Sustainability

RoHS conform	Yes
--------------	-----