




EG403E

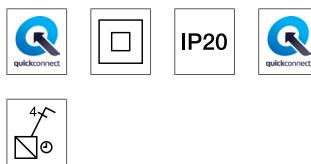

**Weekly time switch 4 channels, digital, 4 modules**

**Technical Features**

**Voltage**

Rated operational voltage Ue	230 - 230 V
------------------------------	-------------

**Frequency**

Frequency	50 - 60 Hz
-----------	------------

**Power**

230 V incandescent and halogen lamp	1500 W
-------------------------------------	--------

**Functions**

Power reserve in years	5 y
With network synchronisation	No
With quartz synchronisation	Yes
Number of function channels	4

**Equipment**

Accuracy per day	0.20 s
With impulse programme	Yes
Number of channels	4

**Settings**

Daily programme	No
Weekly programme	Yes
Annual programme	No

**Use conditions**

Operating temperature	-10 - 50 °C
-----------------------	-------------

**Connection**

Cross-section flexible conductor	0.75 - 2.5 mm <sup>2</sup>
Cross-section rigid conductor	0.75 - 2.5 mm <sup>2</sup>

**Texts**

Type of connection	With quickconnect plug-in terminals
Function	With pulse function Keylock via PIN Presence simulation With operating hours meter

**Dimensions**

Height	90 mm
Width	71 mm
Depth	69 mm

**Main electrical attributes**

Minimum interval between 2 switching times	1 min
--	-------

**Capacity**

Number of modules	4
-------------------	---