


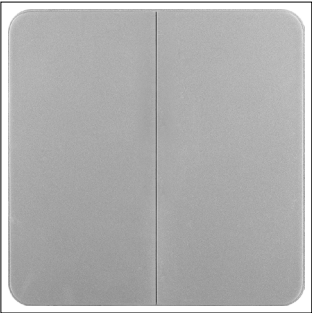

WGDL121NP-12VIG

12V 2G press switch with led;ig

Technical Features

Electric current

|                   |      |
|-------------------|------|
| Switching current | 10 A |
|-------------------|------|

Voltage

|               |       |
|---------------|-------|
| Rated voltage | 250 V |
|---------------|-------|

Architecture

|                           |               |
|---------------------------|---------------|
| Control/operation element | Double rocker |
|---------------------------|---------------|

Materials

|                |                   |
|----------------|-------------------|
| Colour         | Interstellar grey |
| Surface finish | Matt              |
| Treatment      | Varnished         |
| Transparent    | No                |

Dimensions

|        |       |
|--------|-------|
| Height | 90 mm |
| Width  | 90 mm |
| Depth  | 25 mm |

Controls and indicators

|                   |   |
|-------------------|---|
| Number of buttons | 2 |
|-------------------|---|

Connectivity

|                    |                |
|--------------------|----------------|
| Type of connection | Screw terminal |
|--------------------|----------------|

Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
|-------------------------------|------|

Texts

|             |       |
|-------------|-------|
| Switch mode | 1-way |
|-------------|-------|

Suitable for

|       |  |
|-------|--|
| shark |  |
|-------|--|

Sustainability

|              |     |
|--------------|-----|
| RoHS conform | Yes |
|--------------|-----|