


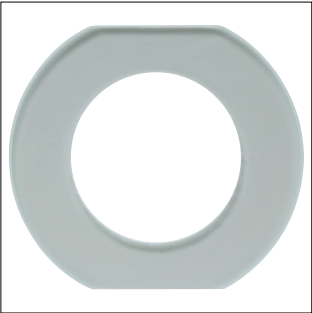

109300

Glass centre frame, clear glossy

Technical Features

Capacity

Number of gangs	1
Number of modules	1

Materials

Colour	Natural
Surface finish	Glossy
Material	Glass
Treatment	Untreated

Dimensions

Height	77 mm
Width	80 mm
Depth	5.80 mm
Number of units horizontal	1
Number of units vertical	1

Accessories

Has labelling field	No
---------------------	----

Installation, mounting

Mounting on	DIN rail
-------------	----------

Safety

Ingress Protection (IP) class	IP20
Impact resistance IK	IK02

Use conditions

Operating temperature	-25 - 70 °C
-----------------------	-------------

Texts

Installation mode	Clamp fastening For combination mounting
-------------------	---

Sustainability

Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes