


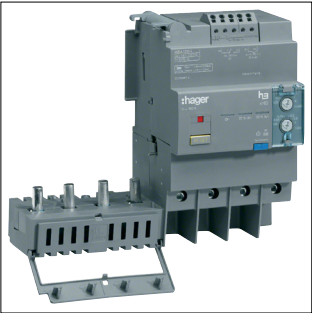

HBA126H

Electronic earth leakage add-on block 4P 125A I_{dn} adjustable, time delay

Technical Features

Electric current

Rated current	125 A
Rated residual operating current I _{dn}	30 mA
	100 mA
	300 mA
	1000 mA
	3000 mA
	6000 mA

Architecture

Number of poles	4
-----------------	---

Safety

Residual current type	A HI
-----------------------	------

Voltage

Rated insulation voltage U _i	500 V
Rated impulse withstand voltage U _{imp}	6000 V

Connection

Cross-section of input and output with screws, for massive conductors	2.5 - 95.0 mm ²
Cross-section of input and output with screws, for flexible conductors	2.5 - 70.0 mm ²

Sustainability

RoHS conform	Yes
--------------	-----