


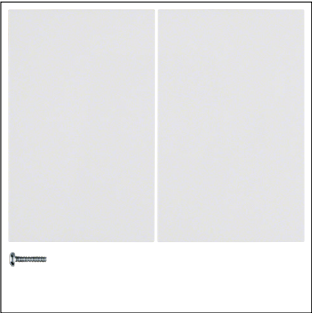

85648179



KNX radio button 4gang quicklink, K.1, p. white glossy

Technical Features

Connectivity

|                           |     |
|---------------------------|-----|
| With bus system KNX radio | Yes |
|---------------------------|-----|

Equipment

|                        |     |
|------------------------|-----|
| Number of channels     | 4   |
| Transmitter duty cycle | 1 % |

Connectivity

|                   |   |
|-------------------|---|
| Receiver category | 2 |
|-------------------|---|

Use conditions

|                       |            |
|-----------------------|------------|
| Operating temperature | -5 - 45 °C |
|-----------------------|------------|

Materials

|        |             |
|--------|-------------|
| Colour | Polar white |
|--------|-------------|

Texts

|          |                                                                                                                                                                                                                                                                                                          |
|----------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Function | Functions for the push-button operation areas up/down or left/right can be freely configured as receiver for controlling the connected load and as transmitter for remote control of a blind, for example<br>Configurable transmission and/or reception behaviour<br>Reset function (to factory setting) |
|----------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|

|            |                             |
|------------|-----------------------------|
| Protection | With dismantling protection |
|------------|-----------------------------|

Sustainability

|              |     |
|--------------|-----|
| RoHS conform | Yes |
|--------------|-----|