


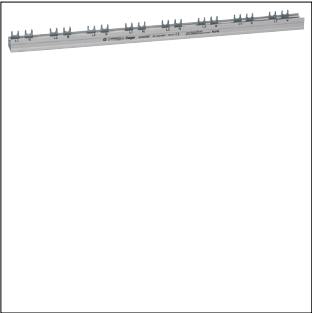

KDN463BZ

24mod Busbar 3P+N with 1mod space (L1N+L2N+L3N+1modspace)

Technical Features

Electric current

Rated current	63 A
---------------	------

Architecture

Number of poles	4
-----------------	---

Dimensions

Length	425 mm
--------	--------

Voltage

Rated impulse withstand voltage Uimp	4000 V
Rated operational voltage Ue	230 - 400 V

Connection

Cross-section rigid conductor	10 mm ²
Connector/plug type	Phase busbar with fork

Capacity

Number of modules	24
-------------------	----

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes