


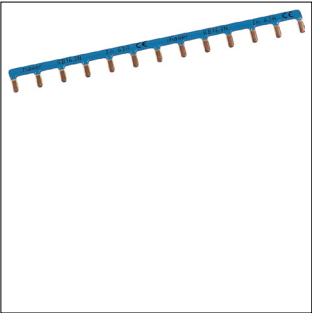

KB163N

Insulated busbar 1P 63A prong 10mm ² blue 13M	
Technical Features	
Electric current	
Rated current	63 A
Architecture	
Number of poles	1
Dimensions	
Length	228 mm
Voltage	
Rated impulse withstand voltage Uimp	4000 V
Rated operational voltage Ue	415 - 415 V
Connection	
Cross-section rigid conductor	10 mm ²
Connector/plug type	Phase busbar with pin
Capacity	
Number of modules	13
Sustainability	
REACH-SVHC free	Yes
RoHS conform	Yes