


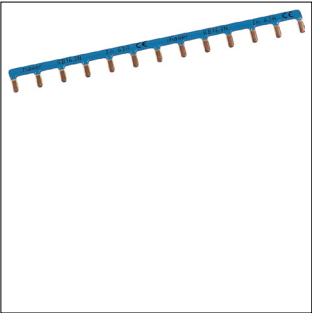

KB163N

Insulated busbar 1P 63A prong 10mm<sup>2</sup> blue 13M

Technical Features

Electric current

|               |      |
|---------------|------|
| Rated current | 63 A |
|---------------|------|

Architecture

|                 |   |
|-----------------|---|
| Number of poles | 1 |
|-----------------|---|

Dimensions

|        |        |
|--------|--------|
| Length | 228 mm |
|--------|--------|

Voltage

|                                      |             |
|--------------------------------------|-------------|
| Rated impulse withstand voltage Uimp | 4000 V      |
| Rated operational voltage Ue         | 415 - 415 V |

Connection

|                               |                       |
|-------------------------------|-----------------------|
| Cross-section rigid conductor | 10 mm <sup>2</sup>    |
| Connector/plug type           | Phase busbar with pin |

Capacity

|                   |    |
|-------------------|----|
| Number of modules | 13 |
|-------------------|----|

Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |