


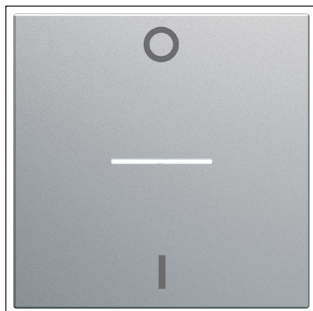

WXD013T

Rocker for switch gallery 0-1 marking with light 2 modules titane

Technical Features

Architecture

|                           |                    |
|---------------------------|--------------------|
| Control/operation element | Single push button |
|---------------------------|--------------------|

Controls and indicators

|                   |   |
|-------------------|---|
| Number of buttons | 1 |
|-------------------|---|

Materials

|                |                    |
|----------------|--------------------|
| Colour         | Titanium           |
| RAL code       | 9006               |
| Surface finish | Satin finish       |
| Material       | Polycarbonate (PC) |
| Treatment      | Varnished          |

Dimensions

|        |          |
|--------|----------|
| Height | 44.60 mm |
| Width  | 44.70 mm |
| Depth  | 8 mm     |

Capacity

|                   |   |
|-------------------|---|
| Number of modules | 2 |
|-------------------|---|

Connectivity

|               |                |
|---------------|----------------|
| Mounting type | Click mounting |
|---------------|----------------|

Equipment

|                                |     |
|--------------------------------|-----|
| Monitoring window/light outlet | Yes |
|--------------------------------|-----|

Accessories

|                     |    |
|---------------------|----|
| Has labelling field | No |
|---------------------|----|

Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP21 |
| Impact resistance IK          | IK05 |

Use conditions

|                       |             |
|-----------------------|-------------|
| Operating temperature | -10 - 35 °C |
|-----------------------|-------------|

Texts

|         |                 |
|---------|-----------------|
| Imprint | Without imprint |
|---------|-----------------|

Suitable for

|         |  |
|---------|--|
| gallery |  |
|---------|--|

Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |