


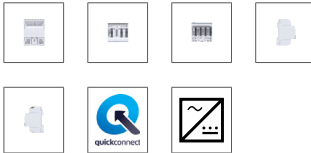

TGA200



### Power supply 24 V DC 1A

#### Technical Features

##### Electric current

Output current	1000 mA
Intensity output 1	1 A

##### Functions

Output voltage adjusted	Yes
-------------------------	-----

##### Power

Current consumption	150 mA
---------------------	--------

##### Frequency

Frequency	50 - 60 Hz
-----------	------------

##### Power

Power consumption standby	0,20 W
---------------------------	--------

##### Connection

Connector/plug type	quickconnect
---------------------	--------------

##### Capacity

Number of modules	4
-------------------	---

##### Voltage

Output voltage	24 - 24 V
----------------	-----------

##### Use conditions

Operating temperature	0 - 45 °C
-----------------------	-----------

##### Dimensions

Height	90 mm
Width	72 mm
Depth	64 mm

##### Sustainability

RoHS conform	Yes
--------------	-----