


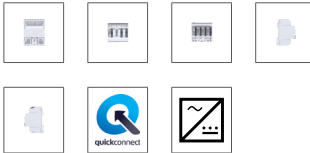

TGA200



Power supply 24 V DC 1A

Technical Features

Electric current

| | |
|--------------------|---------|
| Output current | 1000 mA |
| Intensity output 1 | 1 A |

Functions

| | |
|-------------------------|-----|
| Output voltage adjusted | Yes |
|-------------------------|-----|

Power

| | |
|---------------------|--------|
| Current consumption | 150 mA |
|---------------------|--------|

Frequency

| | |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

Power

| | |
|---------------------------|--------|
| Power consumption standby | 0.20 W |
|---------------------------|--------|

Connection

| | |
|---------------------|--------------|
| Connector/plug type | quickconnect |
|---------------------|--------------|

Capacity

| | |
|-------------------|---|
| Number of modules | 4 |
|-------------------|---|

Voltage

| | |
|----------------|-----------|
| Output voltage | 24 - 24 V |
|----------------|-----------|

Use conditions

| | |
|-----------------------|-----------|
| Operating temperature | 0 - 45 °C |
|-----------------------|-----------|

Dimensions

| | |
|--------|-------|
| Height | 90 mm |
| Width | 72 mm |
| Depth | 64 mm |

Sustainability

| | |
|--------------|-----|
| RoHS conform | Yes |
|--------------|-----|