




EE880

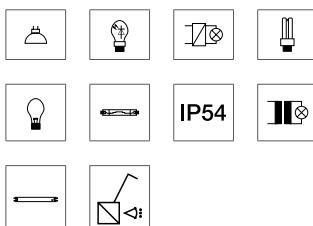

Motion detector IR for corridor, wall mounted, white

Technical Features

Detection

Detection angle	360 - 360
Type of sensor	Movement detector

Settings

Time delay	5 S - 15 Min
------------	--------------

Lighting

Response brightness adjustable	2 - 1000 lx
--------------------------------	-------------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Dimensions

Width	123 mm
Recommended installation height	3 - 3 m

Use conditions

Operating temperature	-20 - 50 °C
-----------------------	-------------

Materials

Colour	White
Material	Acrylonitrile-Butadiene-Styrene (ABS) Polycarbonate (PC) Plastic

Safety

Ingress Protection (IP) class	IP54
-------------------------------	------

Installation, mounting

Mounting on	Surface mounting
Suitable for outdoor usage	Yes

Texts

Function	Parallel connection of several detectors in order to expand the detection area
Installation mode	For ceiling mounting