


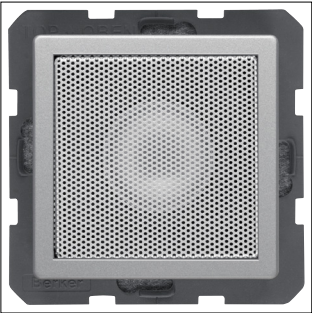

28826084

Loudspeaker Q.x alu velvety lacquered

Technical Features

Resistance

Impedance	4 Ω
-----------	------------

Frequency

Frequency	170 - 18000 Hz
-----------	----------------

Dimensions

Built-in depth	35 mm
----------------	-------

Materials

Colour	Aluminium
Surface finish	Velvety
Treatment	Varnished

Power

Music power handling	4 W
----------------------	-----

Texts

Installation mode	Without spreader claws
-------------------	------------------------

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes