


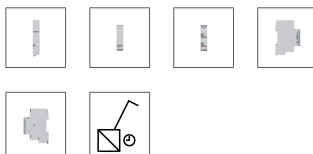

EHN011



### Daily time switch 1 channel, 1 module with reserve

#### Technical Features

##### Equipment

|                    |   |
|--------------------|---|
| Number of channels | 1 |
|--------------------|---|

##### Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

##### Power

|                                     |               |
|-------------------------------------|---------------|
| Power consumption during operation  | 0.50 W        |
| 230 V incandescent and halogen lamp | 1000 W        |
| Power incandescent lamp             | 1000 - 1000 W |

##### Functions

|                             |   |
|-----------------------------|---|
| Number of function channels | 1 |
|-----------------------------|---|

##### Connection

|                                  |                       |
|----------------------------------|-----------------------|
| Number of contacts               | 1                     |
| Cross-section flexible conductor | 1 - 6 mm <sup>2</sup> |
| Cross-section rigid conductor    | 1 - 6 mm <sup>2</sup> |

##### Use conditions

|                       |              |
|-----------------------|--------------|
| Operating temperature | -10 - +50 °C |
|-----------------------|--------------|

##### Capacity

|                   |   |
|-------------------|---|
| Number of modules | 1 |
|-------------------|---|

##### Dimensions

|        |         |
|--------|---------|
| Height | 90 mm   |
| Width  | 17.5 mm |
| Depth  | 60 mm   |

##### Texts

|                   |                          |
|-------------------|--------------------------|
| Switch mode       | NO contact               |
| Installation mode | For mounting on DIN rail |

##### Electric current

|                          |     |
|--------------------------|-----|
| Max. power (cos phi 0,6) | 3 A |
|--------------------------|-----|

##### Endurance

|                                                                  |       |
|------------------------------------------------------------------|-------|
| Electrical durability at nominal load in AC1 in operating cycles | 50000 |
|------------------------------------------------------------------|-------|

##### Texts

|                    |                      |
|--------------------|----------------------|
| Type of connection | With screw terminals |
|--------------------|----------------------|

##### Voltage

|                                          |             |
|------------------------------------------|-------------|
| Rated operational voltage U <sub>e</sub> | 230 - 240 V |
|------------------------------------------|-------------|

##### Power

|                         |     |
|-------------------------|-----|
| Power loss at full load | 1 W |
|-------------------------|-----|

##### Settings

|                         |                           |
|-------------------------|---------------------------|
| Programme cycles        | Programme cycle: 24 hours |
| Shortest switching time | 15 min                    |

##### Lighting

|                |       |
|----------------|-------|
| LED lamp power | 300 W |
|----------------|-------|

##### Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |