




EHN011

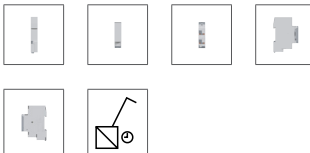

Daily time switch 1 channel, 1 module with reserve

Technical Features

Equipment

| | |
|--------------------|---|
| Number of channels | 1 |
|--------------------|---|

Frequency

| | |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

Power

| | |
|-------------------------------------|---------------|
| Power consumption during operation | 0.50 W |
| 230 V incandescent and halogen lamp | 1000 W |
| Power incandescent lamp | 1000 - 1000 W |

Functions

| | |
|-----------------------------|---|
| Number of function channels | 1 |
|-----------------------------|---|

Connection

| | |
|----------------------------------|-----------------------|
| Number of contacts | 1 |
| Cross-section flexible conductor | 1 - 6 mm ² |
| Cross-section rigid conductor | 1 - 6 mm ² |

Use conditions

| | |
|-----------------------|--------------|
| Operating temperature | -10 - +50 °C |
|-----------------------|--------------|

Capacity

| | |
|-------------------|---|
| Number of modules | 1 |
|-------------------|---|

Dimensions

| | |
|--------|---------|
| Height | 90 mm |
| Width | 17.5 mm |
| Depth | 60 mm |

Texts

| | |
|-------------------|--------------------------|
| Switch mode | NO contact |
| Installation mode | For mounting on DIN rail |

Electric current

| | |
|--------------------------|-----|
| Max. power (cos phi 0,6) | 3 A |
|--------------------------|-----|

Endurance

| | |
|--|-------|
| Electrical durability at nominal load in AC1 in operating cycles | 50000 |
|--|-------|

Texts

| | |
|--------------------|----------------------|
| Type of connection | With screw terminals |
|--------------------|----------------------|

Voltage

| | |
|------------------------------|-------------|
| Rated operational voltage Ue | 230 - 240 V |
|------------------------------|-------------|

Power

| | |
|-------------------------|-----|
| Power loss at full load | 1 W |
|-------------------------|-----|

Settings

| | |
|-------------------------|---------------------------|
| Programme cycles | Programme cycle: 24 hours |
| Shortest switching time | 15 min |

Lighting

| | |
|----------------|-------|
| LED lamp power | 300 W |
|----------------|-------|

Sustainability

| | |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform | Yes |