


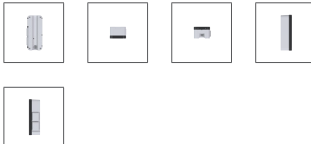

XEV1K1T2



### EV Charging station witty 1x11/22kW 3P T2 IP55 with key

#### Technical Features

##### Power

Power per charging point	22 kW
Connected load	11 - 22 kW

##### Frequency

Frequency	50 - 60 Hz
-----------	------------

##### Power supply

Number of phases for power supply	3
-----------------------------------	---

##### Connectivity

Number of charging points	1
---------------------------	---

##### Functions

With load management	No
----------------------	----

##### Equipment

Number of house sockets	0
With circuit breaker	No
With emergency release at power failure	Yes

##### Connection

Connector/plug type	Type 2S
---------------------	---------

##### Dimensions

Dimensions	553.50 x 237 mm
Height	553.50 mm
Width	237 mm
Depth	173 mm

##### Installation, mounting

Mounting on	Wall mounting
-------------	---------------

##### Safety

Ingress Protection (IP) class	IP55
Impact resistance IK	IK10

##### Use conditions

Operating temperature	-25 - 50 °C
-----------------------	-------------

##### Materials

Material	Plastic
----------	---------