


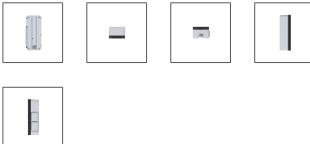

XEV1K11T2



**EV Charging station witty 1x11/22kW 3P T2 IP55 with key**

**Technical Features**

**Power**

Power per charging point	22 kW
Connected load	11 - 22 kW

**Frequency**

Frequency	50 - 60 Hz
-----------	------------

**Power supply**

Number of phases for power supply	3
-----------------------------------	---

**Connectivity**

Number of charging points	1
---------------------------	---

**Functions**

With load management	No
----------------------	----

**Equipment**

Number of house sockets	0
With circuit breaker	No
With emergency release at power failure	Yes

**Connection**

Connector/plug type	Type 2S
---------------------	---------

**Dimensions**

Dimensions	553.50 x 237 mm
Height	553.50 mm
Width	237 mm
Depth	173 mm

**Installation, mounting**

Mounting on	Wall mounting
-------------	---------------

**Safety**

Ingress Protection (IP) class	IP55
Impact resistance IK	IK10

**Use conditions**

Operating temperature	-25 - 50 °C
-----------------------	-------------

**Materials**

Material	Plastic
----------	---------