


EUD100

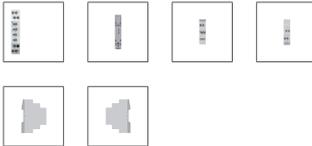

On-delay voltage and phase control relay 1P+N/3P(N) 1 Change over contact

Technical Features

Frequency

Frequency 50 - 50 Hz

Tripping

Max. permitted off-delay time 10 s

Dimensions

Height 87 mm

Width 17.50 mm

Depth 65 mm

Sustainability

Halogen free Yes

REACH-SVHC free Yes

RoHS conform Yes