




80262160

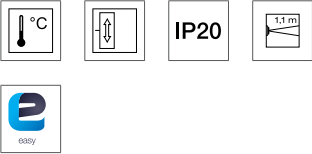

R.x KNX (TP+EASY) Movement detector module 1,10m

Technical Features

Dimensions	
Recommended installation height	1.10 - 1.10 m
Settings	
Supported configuration mode	ETS easy
Minimal duty cycle	10 s
Functions	
Maximal duty cycle	30 min
Connectivity	
With bus system KNX radio	No
Voltage	
Operating voltage over bus	21 - 32 V
Scope of delivery	
Bus connection included	Yes
Electric current	
Bus current consumption data transfer	10 mA
Lighting	
Response brightness adjustable	5 - 1000 lx
Detection	
Detection angle adjustable	45 - 90 °
Detection angle horizontal	90 - 180
Use conditions	
Operating temperature	-5 - 45 °C
Materials	
Material	Metal Plastic
Texts	
Push button	With button for automatic/permanent ON/permanent OFF
Operating mode	With test mode Master/slave operation for covering large detection areas With 3 operating modes: automatic/permanent ON/permanent OFF
Function	Presence simulation With party function
Installation mode	With spreader claws With dismantling protection
Sustainability	
RoHS conform	Yes