


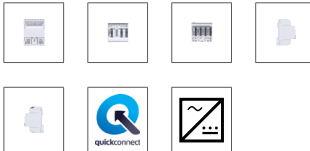

TGA200



**Power supply 24 V DC 1A**

**Technical Features**

**Electric current**

Output current	1000 mA
Intensity output 1	1 A

**Functions**

Output voltage adjusted	Yes
-------------------------	-----

**Power**

Current consumption	150 mA
---------------------	--------

**Frequency**

Frequency	50 - 60 Hz
-----------	------------

**Power**

Power consumption standby	0.20 W
---------------------------	--------

**Connection**

Connector/plug type	quickconnect
---------------------	--------------

**Capacity**

Number of modules	4
-------------------	---

**Voltage**

Output voltage	24 - 24 V
----------------	-----------

**Use conditions**

Operating temperature	0 - 45 °C
-----------------------	-----------

**Dimensions**

Height	90 mm
Width	72 mm
Depth	64 mm

**Sustainability**

RoHS conform	Yes
--------------	-----