


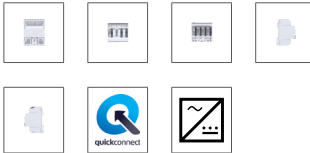

TGA200



Power supply 24 V DC 1A

Technical Features

Electric current

Output current	1000 mA
Intensity output 1	1 A

Functions

Output voltage adjusted	Yes
-------------------------	-----

Power

Current consumption	150 mA
---------------------	--------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Power

Power consumption standby	0.20 W
---------------------------	--------

Connection

Connector/plug type	quickconnect
---------------------	--------------

Capacity

Number of modules	4
-------------------	---

Voltage

Output voltage	24 - 24 V
----------------	-----------

Use conditions

Operating temperature	0 - 45 °C
-----------------------	-----------

Dimensions

Height	90 mm
Width	72 mm
Depth	64 mm

Sustainability

RoHS conform	Yes
--------------	-----