




EEN100

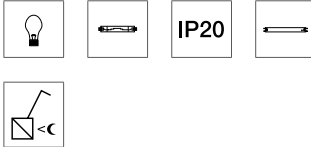

**Twilight switch 1 channel, 1M, wall mounted cell**

**Technical Features**

**Frequency**

Frequency 50 - 60 Hz

**Voltage**

Rated operational voltage U<sub>e</sub> 230 - 230 V

**Settings**

Switch on delay time 60 s

**Use conditions**

Operating temperature -5 - +45 °C

Storage/transport temperature -25 - +70 °C

**Connection**

Cross-section flexible conductor 1.5 - 6 mm<sup>2</sup>

Cross-section rigid conductor 1.5 - 6 mm<sup>2</sup>

**Capacity**

Number of modules 1

**Texts**

Installation mode For mounting on DIN rail  
Extension sensor for wall and ceiling mounting

Type of connection With screw terminals

**Electric current**

Switching current 10 A

**Dimensions**

Height 83 mm

Width 17.80 mm

Depth 65 mm

**Sustainability**

RoHS conform Yes