




80660100

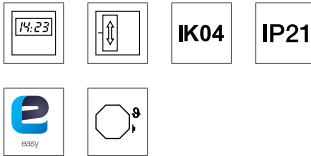

**KNX room cont., colourdisplay, intg bus coupling unit, KNX**

**Technical Features**

**Installation, mounting**

Mounting on Flush mounting

**Use conditions**

Operating temperature -5 - 45 °C

**Electric current**

Bus current consumption data transfer 10 mA

**Dimensions**

Built-in depth 32 mm  
 Built-in depth flush-mounted boxes 26 mm  
 Height 71 mm  
 Width 71 mm  
 Depth 46.70 mm

**Equipment**

Number of actuation points 3

**Controls and indicators**

With LED indication Yes

**Materials**

Colour Black  
 RAL code 9005  
 Material Thermoplastic

**Screen**

With display Yes

**Texts**

Function With keylock  
With holiday switching  
With frost protection function  
 Installation mode With spreader claws  
For flush-mounted and hollow wall mounting  
For single mounting  
For vertical mounting  
 Temperature Additional connection for external temperature sensor  
Comfort, standard and night temperature  
Temperature measurement via internal and/or connectable  
Temperature sensor with average determination

**Scope of delivery**

Bus connection included Yes

**Sustainability**

RoHS conform Yes