




80660100

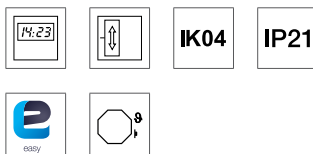

KNX room cont., colourdisplay, intg bus coupling unit, KNX

Technical Features

Installation, mounting

Mounting on Flush mounting

Use conditions

Operating temperature -5 - 45 °C

Electric current

Bus current consumption data transfer 10 mA

Dimensions

Built-in depth 32 mm
 Built-in depth flush-mounted boxes 26 mm
 Height 71 mm
 Width 71 mm
 Depth 46.70 mm

Equipment

Number of actuation points 3

Controls and indicators

With LED indication Yes

Materials

Colour Black
 RAL code 9005
 Material Thermoplastic

Screen

With display Yes

Texts

Function With keylock
With holiday switching
With frost protection function
 Installation mode With spreader claws
For flush-mounted and hollow wall mounting
For single mounting
For vertical mounting
 Temperature Additional connection for external temperature sensor
Comfort, standard and night temperature
Temperature measurement via internal and/or connectable
Temperature sensor with average determination

Sustainability

RoHS conform Yes